


connecting cable KMYZ-9-24-5-LED-PUR-B

Part number: 193689

FESTO

highly flexible, with integrated holding current reduction, for solenoid valves CPE10/14-M1BH.

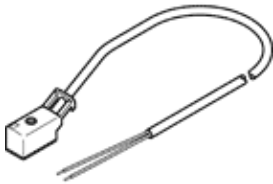

Data sheet

Feature	Value
Assembly position	Any
Additional functions	Reduction of holding current
Switching position indicator	LED
CE mark (see declaration of conformity)	to EU directive for EMC
Protection class	IP65
Ambient temperature	-10 ... 50 °C
Tightening torque	0.25 Nm
Product weight	90 g
Electrical connection	Angled socket / cable Square design/open end 2-pin / 2-wire
Cable structure	2x0,25
Cable diameter	3.4 mm
Cable length	5 m
Protective earth connection	Not available
Mounting type	On solenoid valve with M2 central screw
Materials note	Conforms to RoHS
Materials information, housing	PA
Materials information, cable sheaths	TPE-U(PUR)
Material information for crimp connectors	Bronze