


Operator unit SPC200-MMI-1F

Part number: 194018

FESTO

For commissioning, programming and diagnosis.
Discontinued, available through 2007

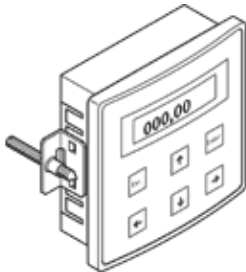

Data sheet

Feature	Value
Configuration support	EDS file
Display	2x16 characters LCD-Display
Control elements	6 keys Membrane keypad
Nominal operating voltage DC	24 V
Typical current consumption, plug-in module	50 mA
CE symbol (see declaration of conformity)	according to EU-EMV guideline
Protection class	IP65 to IEC 60529
Ambient temperature	-5 ... 50 °C
Product weight	225 g
MMI interface design	RS232C Electrical isolation 9600 - 115200 Baud 8 bits of data 1 stop bit even parity No handshake
Electrical connection, operating voltage	Terminal strip 3-pin
Electrical connection, MMI-1	Plug SUB-D 9-pin