

# service unit

## FRCS-1-D-7-O-MAXI

 

Part number: 194965  
Classic - do not use for new projects

FESTO

Filter/pressure regulator/lubricator combination,  
D series, with lockable regulator head.

Modern alternatives can be found by entering the first four characters  
of the type code in the search field.

Type to be discontinued. Available until 2022. See Support Portal for  
alternative products.

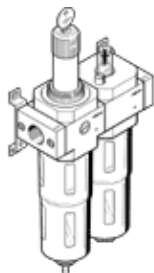

## Data sheet

Feature	Value
Size	Maxi
Series	D
Actuator lock	Rotary knob with integrated lock
Assembly position	Vertical +/- 5°
Condensate drain	manual rotary
Design structure	Filter regulator without pressure gauge proportional standard mist lubricator
Max. condensate volume	80 cm <sup>3</sup>
Grade of filtration	40 µm
Bowl guard	Metal bowl guard
Pressure gauge	Prepared for G1/4
Operating pressure	1 ... 16 bar
Pressure regulation range	0.5 ... 7 bar
Max. pressure hysteresis	0.4 bar
Standard nominal flow rate	8,700 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [-::-]
Medium temperature	-10 ... 60 °C
Ambient temperature	-10 ... 60 °C
Product weight	2,620 g
Mounting type	Line installation with accessories
Pneumatic connection, port 1	G1
Pneumatic connection, port 2	G1
Material housing	Zinc die-casting
Material bowl	PC