 



Service unit FRCS-1-D-7-DI-MAXI

Part number: 194988

FESTO

Filter/regulator/lubricator combination, S series, with lockable regulator head.

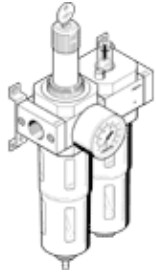

Data sheet

Feature	Value
Size	Maxi
Series	D
Actuator lock	Rotary knob with integrated lock
Assembly position	Vertical +/- 5°
Grade of filtration	40 µm
Condensate drain	manual rotary
Design structure	Filter regulator with pressure gauge proportional standard mist lubricator
Max. condensate volume	43 cm ³
Bowl guard	Metal bowl guard
Pressure gauge	with pressure gauge
Pressure control range	0.5 ... 7 bar
Inlet pressure 1	1 ... 16 bar
Max. pressure hysteresis	0.4 bar
Standard nominal flow rate	5,200 l/min
Operating medium	Compressed air
Medium temperature	-10 ... 60 °C
Ambient temperature	-10 ... 60 °C
Product weight	2,600 g
Mounting type	Line installation
Pneumatic connection, port 1	G1
Pneumatic connection, port 2	G1
Materials information, housing	Zinc die-casting
Materials information for bowl	PC