


connecting cable KMYZ-9-24-M8-2,5-LED-B

Part number: 196065

FESTO

For CPE-M1BH and CPE10SC solenoid valves, and MPV multi-pin distributor.

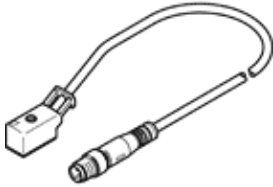

Data sheet

Feature	Value
Assembly position	Any
Additional functions	Reduction of holding current
Switching position indicator	LED
CE mark (see declaration of conformity)	to EU directive for EMC
Protection class	IP65
Ambient temperature	-10 ... 50 °C
Tightening torque	0.25 Nm
Product weight	54 g
Electrical connection	angled socket / straight plug square design / M8x1 2-pin / 3-pin
Cable structure	2x0,25
Cable diameter	3.4 mm
Cable length	2.5 m
Protective earth connection	Not available
Mounting type	On solenoid valve with M2 central screw
Materials note	Conforms to RoHS
Materials information, housing	PA
Materials information, cable sheaths	TPE-U(PUR)
Material information for crimp connectors	Bronze