


# Valve terminal CDVI5.0

Part number: 197648

FESTO

Valve terminal CDVI, Clean Design.

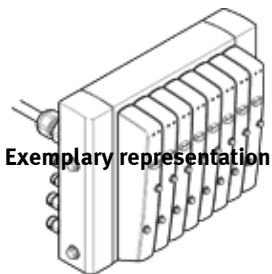

## Data sheet

Overall data sheet – Individual values depend upon your configuration.

Feature	Value
Valve function	3/2 closed, monostable 3/2 open/closed, monostable 3/2 open, monostable 2/2 open, monostable 2/2 closed, monostable 5/3 closed 5/3 exhausted 5/3 pressurised 5/2 bistable 2x3/2 closed, monostable 2x3/2 open, monostable 5/2 monostable
Valve size	24 mm
Max. standard nominal flow rate	650 l/min at 24 mm
Operating pressure	-0.9 ... 10 bar
Authorisation	C-Tick
Based on the standard	ISO 14159 EN 1672-2
Nominal operating voltage DC	24 V
Permissible voltage fluctuation	+/- 10 %
CE mark (see declaration of conformity)	to EU directive for EMC
Corrosion resistance classification CRC	3
Medium temperature	-5 ... 50 °C
Protection class	IP65 IP67 IP66 NEMA 4
Ambient temperature	-5 ... 50 °C
Electrical connection	Multi-pin plug Fieldbus
Switching position indicator	LED
Materials note	Conforms to RoHS
Type of actuation	electrical
Electrical I/O system	Yes
Valve terminal type	15
Max. number of valve positions	16
Valve terminal structure	modular