


Distributor block FR-8-1/8

Part number: 2077

FESTO

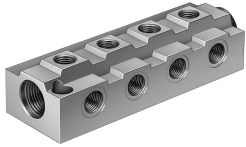

Data sheet

| Feature | Value |
|---|--|
| Nominal size | 8.6 mm |
| Mounting position | optional |
| Operating pressure complete temperature range | 0 bar...16 bar |
| Operating medium | Compressed air to ISO 8573-1:2010 [7:-:-] |
| Note on operating and pilot medium | Lubricated operation possible (in which case lubricated operation will always be required) |
| Corrosion resistance class CRC | 0 - No corrosion stress |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L |
| Ambient temperature | -10 °C...60 °C |
| Nominal torque | 12.5 Nm |
| Tolerance for nominal tightening torque | ± 20% |
| Product weight | 135 g |
| Number of outputs | 8 |
| Number of supply lines | 1 |
| Pneumatic connection, port 1 | Female thread G3/8 |
| Pneumatic connection, port 2 | Female thread G1/8 |
| Note on materials | RoHS-compliant |
| Material housing | Die-cast aluminium |