


Throttle valve GRO-1/4

Part number: 2109

FESTO

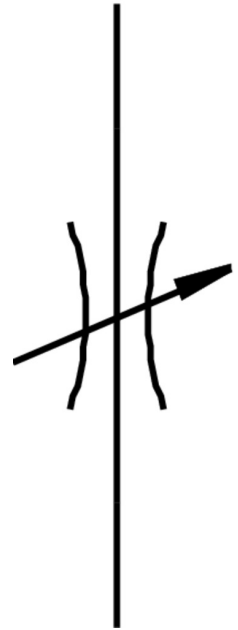

Data sheet

Feature	Value
Valve function	Flow control function
Pneumatic connection, port 1	G1/4
Pneumatic connection, port 2	G1/4
Adjustment component	Knurled screw
Type of mounting	In-line installation
Standard nominal flow rate in flow control direction	350 l/min
Operating pressure	0 bar...10 bar
Ambient temperature	-20 °C...60 °C
Material housing	Wrought aluminium alloy
Mounting position	optional
Operating medium	Compressed air to ISO 8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (in which case lubricated operation will always be required)
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Media temperature	-20 °C...60 °C
Product weight	80 g
Note on materials	RoHS-compliant
Material seals	NBR

Feature	Value
Material adjusting screw	Steel Galvanised