


# axial kit EAMM-A-D60-60G-G2

Part number: 2256696

FESTO

Suitable for electric drives.

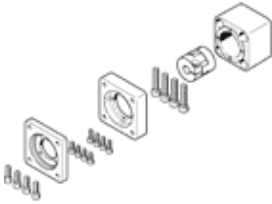

## Data sheet

Feature	Value
Assembly position	Any
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Protection class	IP40
Ambient temperature	-10 ... 60 °C
Transferable torque	17 Nm
Product weight	1,350 g
Interface code, actuator	D60A D60B D60C
Interface code, motor in	60G 80G
Materials note	Conforms to RoHS