


# Axial kit EAMM-A-D60-100A-S1

Part number: 2256700

FESTO

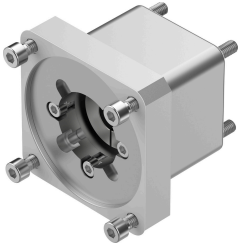

## Data sheet

Feature	Value
Mounting position	optional
LABS (PWIS) conformity	VDMA24364 zone III
Storage temperature	-25 °C...60 °C
Relative air humidity	0 - 95%
Degree of protection	IP65
Ambient temperature	-10 °C...60 °C
Transmittable torque	17 Nm
Product weight	1170 g
Interface code, actuator	D60A D60B
Interface code, motor in	100A
Note on materials	RoHS-compliant