


gear unit EMGC-67-A-G1-SEC-67

Part number: 2321480
Product to be discontinued

FESTO

Type to be discontinued. Available until 2026. See Support Portal for alternative products.

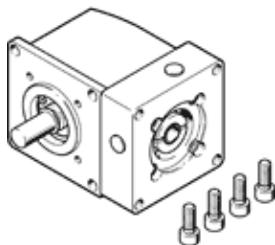

Data sheet

Feature	Value
Gear unit flange size	67 mm
Motor flange size	67 mm
Torsional backlash	0.67 deg
Type of gear unit	Right-angle gear unit
Gear unit ratio	1:1
Max. input speed	4,500 1/min
Operating temperature of gear unit	-20 ... 90 °C
PWIS conformity	VDMA24364 zone III
Protection class	IP54
Continuous output torque	2 Nm
Mass moment of inertia of gear unit	0.09 kgcm ²
Max. output torque	2.1 Nm
Max. efficiency	90 %
Torsional resistance	0.105 Nm/arcmin
Product weight	930 g
Interface code, motor out	67A
Interface code, motor in	67A
Materials note	Conforms to RoHS