


# butterfly valve

## VZFB-SZ-21/2"-TT-V4V4E

Part number: 2468252  
 Product to be discontinued

FESTO

Nominal width 2 1/2", with thread, SMS 1145, EPDM, material 1.4404.  
 Type to be discontinued. Available until 2022. See Support Portal for alternative products.

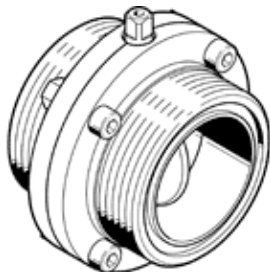

### Data sheet

| Feature                                 | Value  |
|---|--|
| Design structure                        | 2-way disc valve                             |
| Type of actuation                       | manual                                       |
| Sealing principle                       | soft   |
| Assembly position                       | Any  |
| Mounting type                           | Line installation                            |
| Process valve connection                | Male thread/male thread                      |
| Nominal diameter DN                     | 2 1/2"                                       |
| Flow direction                          | reversible                                   |
| Nominal pressure of process valve       | 10   |
| Actuation torque                        | 15 Nm  |
| Based on the standard                   | SMS 1145                                     |
| Medium                                  | Water<br>Neutral fluids                      |
| Medium temperature                      | -10 ... 120 °C                               |
| Materials note                          | Contains PWIS substances<br>Conforms to RoHS |
| Food-safe                               | See Supplementary material information       |
| Material housing                        | High alloy steel, non-corrosive              |
| Material number for housing             | 1.4404                                       |
| Material disc                           | High alloy steel, non-corrosive              |
| Material number for disc                | 1.4404                                       |
| Material shaft                          | High alloy steel, non-corrosive              |
| Material number for shaft               | 1.4404                                       |
| Product weight                          | 2,600 g                                      |
| Corrosion resistance classification CRC | 4 - Very high corrosion stress               |