


Round cylinder DGS-40-140

Part number: 2476
Product to be discontinued

FESTO

Without end-position cushioning

Type to be discontinued. Available until 2016. See Support Portal for alternative products.

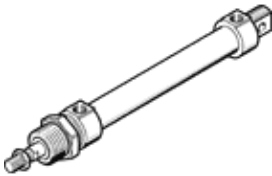

Data sheet

Feature	Value
Stroke	140 mm
Piston diameter	40 mm
Cushioning	No cushioning
Position detection	No
Variants	Single-ended piston rod
Operating pressure	0.6 ... 10 bar
Mode of operation	double-acting
Ambient temperature	-20 ... 80 °C
Theoretical force at 6 bar, return stroke	633 N
Theoretical force at 6 bar, advance stroke	754 N
Pneumatic connection	G1/4