


Sub-base VABP-S1-1V1G-G14-2M-R3

Part number: 2614863

FESTO

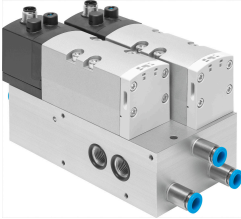

Data sheet

Feature	Value
Construction width	42 mm
Function port 32	G1/8
Function port 34	G1/8
Pneumatic port 22	Sub-base G1/4
Pneumatic port 44	Sub-base G1/4
Mounting position	optional
Operating pressure	0 bar...16 bar
Pilot pressure	3 bar...8 bar
Standard nominal flow rate	1400 l/min
Operating medium	Compressed air to ISO 8573-1:2010 [6:4:4]
Corrosion resistance class CRC	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Media temperature	0 °C...50 °C
Ambient temperature	0 °C...50 °C
Product weight	2480 g
Pilot air port 14	G1/8
Pneumatic connection, port 2	G1/4
Pneumatic connection, port 4	G1/4
Note on materials	RoHS-compliant
Material manifold rail	Wrought aluminium alloy
Material o-ring	NBR
Material screws	Steel