


Round cylinder DGS-25- -

Part number: 2710
Product to be discontinued

FESTO

[Variants without end-position cushioning](#)

Type to be discontinued. Available until 2016. See Support Portal for alternative products.

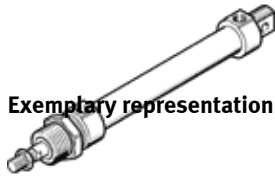

Exemplary representation



Data sheet

Feature	Value
Stroke	1 ... 500 mm
Piston diameter	25 mm
Cushioning	No cushioning
Position detection	No
Variants	Single-ended piston rod
Operating pressure	1 ... 12 bar
Mode of operation	double-acting
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Ambient temperature	-20 ... 80 °C
Theoretical force at 6 bar, return stroke	247 N
Theoretical force at 6 bar, advance stroke	295 N
Pneumatic connection	G1/8