


# Round cylinder DGS-40- -

Part number: 2711  
Product to be discontinued

FESTO

Without end-position cushioning

Type to be discontinued. Available until 2016. See Support Portal for alternative products.

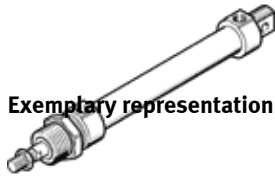

Exemplary representation



## Data sheet

Feature	Value
Stroke	1 ... 2,000 mm
Piston diameter	40 mm
Cushioning	No cushioning
Position detection	No
Variants	Single-ended piston rod
Operating pressure	0.6 ... 10 bar
Mode of operation	double-acting
Ambient temperature	-20 ... 80 °C
Theoretical force at 6 bar, return stroke	633 N
Theoretical force at 6 bar, advance stroke	754 N
Pneumatic connection	G1/4