


# Sub-base VABP-S1-2V1G-G38-2M-A1

Part number: 2738672

FESTO

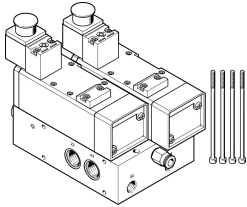

## Data sheet

| Feature                        | Value                                     |
|--------------------------------|---|
| Construction width             | 54 mm                                     |
| Function port 32               | G1/4                                      |
| Function port 34               | G1/4                                      |
| Pneumatic port 22              | Sub-base<br>G3/8                          |
| Pneumatic port 44              | Sub-base<br>G3/8                          |
| Mounting position              | optional                                  |
| Operating pressure             | 0 bar...16 bar                            |
| Pilot pressure                 | 3 bar...8 bar                             |
| Standard nominal flow rate     | 2000 l/min                                |
| Operating medium               | Compressed air to ISO 8573-1:2010 [6:4:4] |
| Corrosion resistance class CRC | 0 - No corrosion stress                   |
| LABS (PWIS) conformity         | VDMA24364-B1/B2-L                         |
| Media temperature              | 0 °C...50 °C                              |
| Ambient temperature            | 0 °C...50 °C                              |
| Product weight                 | 3400 g                                    |
| Pilot air port 14              | G1/8                                      |
| Pneumatic connection, port 2   | G3/8                                      |
| Pneumatic connection, port 4   | G3/8                                      |
| Note on materials              | RoHS-compliant                            |
| Material manifold rail         | Wrought aluminium alloy                   |
| Material o-ring                | NBR                                       |
| Material screws                | Steel                                     |