


# guide unit EAGF-V2-KF-40-200

Part number: 2782976

★ Core product range

For electric cylinder ESBF.

FESTO

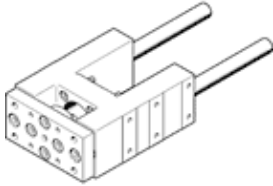

## Data sheet

Feature	Value
Size	40
Stroke	200 mm
Reversing backlash	0 µm
Assembly position	Any
Guide	Recirculating ball bearing guide
Design structure	Guide
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364-B2-L
Ambient temperature	-20 ... 80 °C
Max. force Fy	1,000 N
Max. force Fy static	1,260 N
Max. force Fz	1,000 N
Max. force Fz static	1,260 N
Max. torque Mx	44 Nm
Max. torque Mx static	55 Nm
Max. torque My	52 Nm
Max. torque My static	65 Nm
Max. torque Mz	52 Nm
Max. torque Mz static	65 Nm
Displacement force	15 N
Moving mass	1,923 g
Product weight	3,157 g
Centre of gravity of moving mass with 0 mm stroke	38 mm
Additional allowance for centre of gravity of moving mass per 10 mm stroke	4.2 mm
Mounting type	with internal (female) thread
Materials note	Conforms to RoHS
Material of guide component	Heat-treatment steel
Material housing	Wrought Aluminium alloy Anodised
Material yoke plate	Steel