


# bellows kit EADB-V2-50-S301-400

Part number: 2828842

FESTO

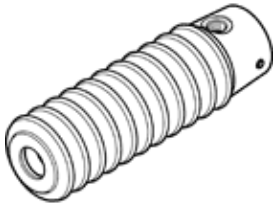

## Data sheet

Feature	Value
Outside diameter	93 mm
Size	50
Stroke range	301 ... 400 mm
Piston rod extension	107 mm
Design	Round
Assembly position	Any
Design structure	Bellows kit with ducted exhaust air
Corrosion resistance classification CRC	3 - High corrosion stress
PWIS conformity	VDMA24364-B2-L
Resistance to media	Dust Chippings Oils Grease Gasolines
Protection class	IP65 to IEC 60529
Ambient temperature	-10 ... 80 °C
Moving mass	280 g
Product weight	377 g
Mounting type	slip-on With threaded pin
Pneumatic connection	G1/4
Materials note	Conforms to RoHS
Material adapter components	Wrought Aluminium alloy Anodised
Material seals	NBR
Material bellows	NBR
Material threaded pin	High alloy steel, non-corrosive