

 

# Solenoid valve

## MZH-3-0,4-LED

Part number: 30217

FESTO

Micro Pneumatic, with solenoid coil and manual override, without plug socket.

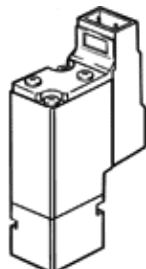

### Data sheet

Feature	Value
Valve function	3/2 closed, single solenoid
Standard nominal flow rate	4 l/min
Operating pressure	0 ... 7 bar
Design structure	Poppet seat
Protection class	IP40 with plug socket
Nominal size	0.4 mm
Type of piloting	direct
Switching time off	13 ms
Switching time on	5 ms
Duty cycle	100%
Characteristic coil data	24V DC: 0,55W
Operating medium	Dried compressed air, lubricated or unlubricated
Medium temperature	-5 ... 50 °C
Ambient temperature	-5 ... 50 °C
Product weight	20 g
Mounting type	with through hole
Pneumatic connection, port 1	Sub-base
Pneumatic connection, port 2	Sub-base
Pneumatic connection, port 3	Sub-base
Materials information for seals	NBR
Materials information, housing	Aluminium die cast