

 

# Solenoid valve

## MZH-3-1,5-L-LED

Part number: 30218

FESTO

Micro Pneumatic, with solenoid coil and manual override, without plug socket.

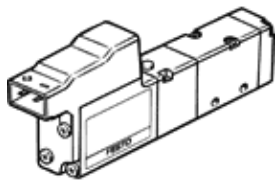

## Data sheet

Feature	Value
Valve function	3/2 closed, single solenoid
Standard nominal flow rate	80 l/min
Operating pressure	2 ... 7 bar
Design structure	Piston slide
Protection class	IP40 with plug socket
Nominal size	1.5 mm
Type of piloting	Piloted
Switching time off	23 ms
Switching time on	7 ms
Duty cycle	100%
Characteristic coil data	24V DC: 0,55W
Operating medium	Dried compressed air, lubricated or unlubricated
Medium temperature	-5 ... 50 °C
Ambient temperature	-5 ... 50 °C
Product weight	30 g
Mounting type	with through hole
Pneumatic connection, port 1	Sub-base Manifold module
Pneumatic connection, port 2	Sub-base Manifold module
Pneumatic connection, port 3	Sub-base Manifold module
Pneumatic connection, port 4	Manifold module
Pneumatic connection, port 5	Manifold module
Materials information for seals	NBR
Materials information, housing	Aluminium die cast