


Series sub-base VIGK-04-D-1-NPT

Part number: 30428

FESTO

For valve terminal

This product is only available if ordered from the Festo Corporation, USA.

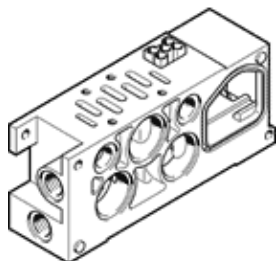

Data sheet

Feature	Value
Width	149 mm
Operating pressure	-0.9 ... 16 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Medium temperature	-10 ... 60 °C
Ambient temperature	-10 ... 60 °C
Authorisation	UL - Recognized (OL)
Mounting method for sub-base	with through hole
Auxiliary pilot air port 12/14	NPT1/8-27
Pneumatic connection, port 1	NPT1/2-14
Pneumatic connection, port 2	NPT1/4-18
Pneumatic connection, port 3	NPT1/2-14
Pneumatic connection, port 4	NPT1/4-18
Pneumatic connection, port 5	NPT1/2-14
Materials information for sub-base	Aluminium die cast