


# Plug socket with cable KMF-1-230AC-2.5

Part number: 30936

FESTO

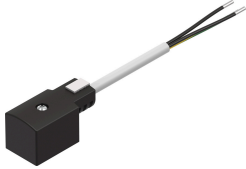

## Data sheet

Feature	Value
Type of mounting	On solenoid valve via M3 central screw
Mounting position	optional
Product weight	170 g
Electrical connection	Socket
Nominal operating voltage AC	230 V
Protective conductor connection	Available
Cable length	2.5 m
Cable diameter	6 mm
Cable structure	3 x 0.75 mm <sup>2</sup>
Degree of protection	IP67 To IEC 60529
Ambient temperature	-20 °C...80 °C
CE mark (see declaration of conformity)	To EU Low Voltage Directive In accordance with EU RoHS Directive
CE marking (see declaration of conformity)	To UK RoHS instructions To UK regulations for electrical equipment
LABS (PWIS) conformity	VDMA24364-B2-L
Material cable sheath	PVC
Material housing	PC POM
Material electrical contact	Bronze