


clevis foot LBG-125

Part number: 31767

FESTO

Provides spherical bearing in conjunction with swivel flange SSNG or rod eye SGS and cylinders DNGU, DNG, DNC.

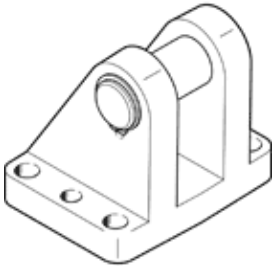

Data sheet

Feature	Value
Size	125
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B2-L
RSBP classification to CD-0033	F5
Ambient temperature	-40 ... 150 °C
Product weight	4,140 g
Materials note	Conforms to RoHS
Material mounting	Nodular graphite cast iron
Material mounting pin	Case-hardened steel
Material lock	Spring steel