


# coupling

## EAMC-67-62-24-25

Part number: 3187895

FESTO

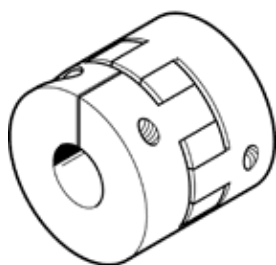

### Data sheet

Feature	Value
Holder diameter 1	24 mm
Holder diameter 2	25 mm
Size	67
Nominal length	62 mm
Assembly position	Any
Max. speed	4,500 1/min
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Ambient temperature	-25 ... 60 °C
Mass moment of inertia	280 kgmm <sup>2</sup>
Transferable torque	143 Nm
Product weight	435 g
Materials note	Conforms to RoHS