


Swivel flange SNGB-80

Part number: 34544
Product to be discontinued

FESTO

For cylinders DNG, DNGU; matching clevis foot mountings LN, LSN.
Type to be discontinued. Available until 2014. See Support Portal for alternative products.

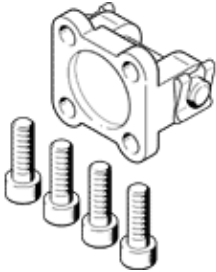

Data sheet

| Feature | Value |
|---|---|
| Size | 80 |
| Based on the standard | ISO 15552 (previously also VDMA 24652, ISO 6431, NF E49 003.1, UNI 10290) |
| Corrosion resistance classification CRC | 2 |
| Ambient temperature | -40 ... 90 °C |
| Product weight | 610 g |
| Materials note | Free of copper and PTFE Conforms to RoHS |
| Material information, mounting | Aluminium die cast |
| Material information, bolt | Steel Galvanised |
| Materials information for bearing | Plastic |
| Screw material data | Steel Galvanised |
| Material information for fuse | Spring steel, galvanised |