 



suction cup VAS-30-1/8-NBR

Part number: 34587
★ Core product range
With sealing ring OL.

FESTO

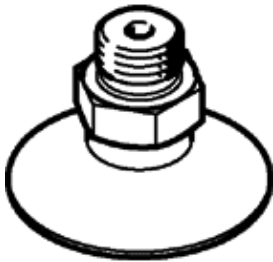

Data sheet

Feature	Value
Nominal size	3 mm
suction cup diameter	30 mm
Effective suction diameter	25 mm
Position of connection	on top
Suction cup shape	round flat
Operating pressure MPa	-0.095 ... 0 MPa
Operating pressure	-0.95 ... 0 bar -13.775 ... 0 psi
Nominal operating pressure	-0.07 MPa -0.7 bar
Nominal operating pressure (psi)	-10.15 psi
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:-:-]
PWIS conformity	VDMA24364-A1-L
Ambient temperature	-20 ... 80 °C
Breakaway force at 70% vacuum	34 N
Retention force at nominal operating pressure	34 N
Mounting thread	G1/8
suction cup mounting	G 1/8
Vacuum connection	G1/8
Colour	Black
Shore hardness	70 +/- 5
Material of threaded plug	Brass
Materials note	Conforms to RoHS
Material suction cup	NBR