


Connecting cable KMYZ-2-24-2,5-LED

Part number: 34997

FESTO

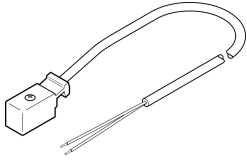

Data sheet

Feature	Value
Maritime classification	See certificate
Switching position indicator	LED
Type of mounting	On solenoid valve via self-tapping screw
Mounting position	optional
Product weight	50 g
Electrical connection	2-pin/2-wire Angled socket/cable Square design/open end
Nominal operating voltage DC	24 V
Current rating at 40° C	1 A
Protective conductor connection	Not available
Cable length	2.5 m
Cable characteristic	Standard
Cable diameter	3.4 mm
Cable structure	2 x 0.25 mm ²
Degree of protection	IP65
Ambient temperature	-10 °C...50 °C
CE mark (see declaration of conformity)	In accordance with EU RoHS Directive
CE marking (see declaration of conformity)	To UK RoHS instructions
LABS (PWIS) conformity	VDMA24364-B2-L
Note on materials	RoHS-compliant
Corrosion resistance class CRC	2 - Moderate corrosion stress
Material cable sheath	TPE-U(PUR)
Material housing	PA
Material electrical contact	Bronze