


Exhaust protection VABD-D3-SN-N12

Part number: 3535104

FESTO

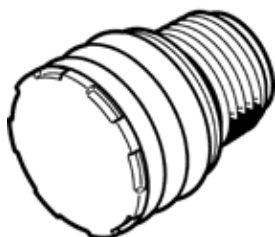

Data sheet

Feature	Value
Assembly position	Any
Operating pressure MPa	0 ... 1.2 MPa
Operating pressure	0 ... 12 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7::-:]
PWIS conformity	VDMA24364 zone III
Protection class	IP65
Ambient temperature	-50 ... 60 °C
Mounting type	Threaded with external (male) thread
Materials note	Conforms to RoHS
Material seals	EPDM
Material vent screw	PA