


suction cup VASB-100-1/4-NBR

Part number: 35416

FESTO

With sealing ring OL.

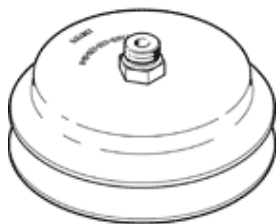

Data sheet

| Feature | Value |
|---|--|
| Nominal size | 4 mm |
| suction cup diameter | 100 mm |
| Effective suction diameter | 85 mm |
| Position of connection | on top |
| Suction cup shape | Round, bellows 1.5 conv |
| Operating medium | Atmospheric air based on ISO 8573-1:2010 [7:-:-] |
| PWIS conformity | VDMA24364-B1/B2-L |
| Ambient temperature | -20 ... 80 °C |
| Breakaway force at 70% vacuum | 397 N |
| Retention force at nominal operating pressure | 397 N |
| Mounting thread | G1/4 |
| suction cup mounting | G 1/4 |
| Vacuum connection | G1/4 |
| Colour | Black |
| Shore hardness | 60 +/- 5 |
| Material of threaded plug | Zinc die-casting |
| Materials note | Conforms to RoHS |
| Material suction cup | NBR |