 



pneumatic valve VL-5-PK-3

Part number: 4504

FESTO

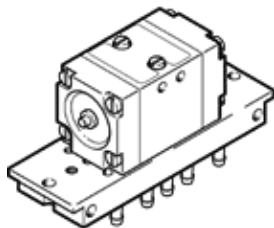

Data sheet

| Feature | Value |
|------------------------------|---|
| Valve function | 5/2 monostable |
| Standard nominal flow rate | 105 l/min |
| Operating pressure | 1.5 ... 8 bar |
| Design structure | Poppet seat |
| Nominal size | 2.5 mm |
| Switching time off | 22 ms |
| Switching time on | 15 ms |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [7:-:-] |
| PWIS conformity | VDMA24364-B1/B2-L |
| Ambient temperature | -10 ... 60 °C |
| Product weight | 130 g |
| Mounting type | On sub-base On mounting frame with through hole Optional |
| Pneumatic connection, port 1 | PK-3 |
| Pneumatic connection, port 2 | PK-3 |
| Pneumatic connection, port 3 | PK-3 |
| Pneumatic connection, port 4 | PK-3 |
| Pneumatic connection, port 5 | PK-3 |
| Materials note | Conforms to RoHS |
| Material of connecting plate | Brass PPS-reinforced |
| Material seals | NBR |
| Material housing | Plastic Zinc die-casting |