


# EMC-filter CAMF-C5-FC

Part number: 4825847

FESTO

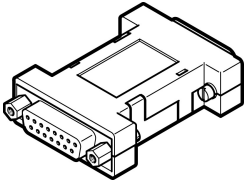

## Data sheet

Feature	Value
Operational voltage range DC	0 V...30 V
Nominal operating voltage DC	24 V
Operational voltage range AC	0 V...30 V
Nominal operating voltage AC	24 V
LABS (PWIS) conformity	VDMA24364-B2-L
Degree of protection	IP30
Note on degree of protection	In assembled state
Ambient temperature	-40 °C...80 °C
Note on materials	RoHS-compliant
Electrical connection 1, function	Field device side
Electrical connection 1, design	Angular
Electrical connection 1, connection type	Socket
Electrical connection 1, cable outlet	Straight
Electrical connection 1, connector system	Sub-D
Electrical connection 1, number of connections/cores	15
Electrical connection 1, used connections/cores	8
Electrical connection 2, function	Controller side
Electrical connection 2, design	Angular
Electrical connection 2, connection type	Plugs
Electrical connection 2, cable outlet	Straight
Electrical connection 2, connector system	Sub-D
Electrical connection 2, number of connections/cores	15
Electrical connection 2, used connections/cores	8
electrical connection 2, type of mounting	2x screw 4-40 UNC-2A
Protocol	HIPERFACE
Housing colour	Silver
Material housing	Metallised plastic