


**coupling**  
**EAMD-56-46-18-23X27**  
Part number: 5063729

**FESTO**

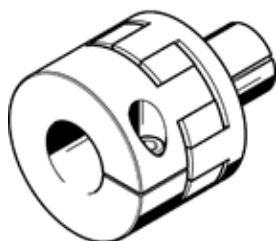

**Data sheet**

<b>Feature</b>	<b>Value</b>
Holder diameter 1	18 mm
Holder diameter 2	23 mm
Size	56
Nominal length	46.5 mm
Assembly position	Any
Max. speed	5,500 1/min
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Ambient temperature	-25 ... 60 °C
Mass moment of inertia	151 kgmm <sup>2</sup>
Transferable torque	57 Nm
Product weight	419 g
Materials note	Conforms to RoHS