


# manifold block MHP2-PR10-5

Part number: 525126

FESTO

For semi in-line valve MHP2-...-HC/TC

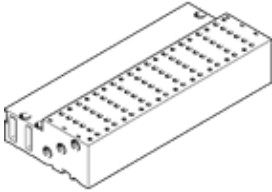

## Data sheet

Feature	Value
Max. number of valve positions	10
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Product weight	597 g
Mounting method for sub-base	with through hole with top-hat rail
Mounting method for valve	with internal (female) thread
Pneumatic connection, port 1	M7
Pneumatic connection, port 3	M7
Pneumatic connection, port 5	M7
Material of connecting plate	Wrought Aluminium alloy