


# manifold block MHA2-PR6-5-M5

Part number: 525129

FESTO

for manifold block valves MHA2-...-HC/TC

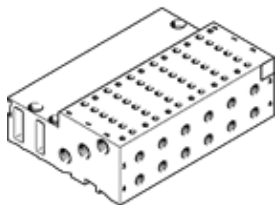

## Data sheet

Feature	Value
Max. number of valve positions	6
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Product weight	426 g
Mounting method for sub-base	with through hole with top-hat rail
Mounting method for valve	with internal (female) thread
Pneumatic connection, port 1	M7
Pneumatic connection, port 2	M5
Pneumatic connection, port 3	M7
Pneumatic connection, port 4	M5
Pneumatic connection, port 5	M7
Material of connecting plate	Wrought Aluminium alloy