

plastic tubing


PAN-V0-10X1,25-BL-20

Part number: 525468
Product to be discontinued

FESTO

Flame retardant

Type to be discontinued. Available until 2019. See Support Portal for alternative products.

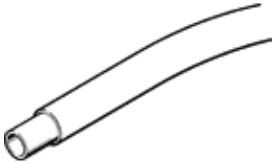

Data sheet

Feature	Value
Outside diameter	12 mm
Bending radius relevant for flow rate	56 mm
Inside diameter	7.5 mm
Min. bending radius	34 mm
Temperature dependent operating pressure	-0.95 ... 12 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-] Water as per manufacturer's declaration at www.festo.com Mineral oil
Material fire test	UL94 V-0 (casing)
Ambient temperature	-30 ... 90 °C
Product weight according to length	0.088 kg/m
Pneumatic connection	For push-in connector outside diameter 10 mm
Colour	blue
Shore hardness	A 72 +/-4 D 57 +/-3
Materials note	Conforms to RoHS
Material tubing	Polyamide 12 PVC-P