


Manifold block VIGK-04-D-1-3/8

Part number: 525569

FESTO

For valve terminal 04, high flow rate, size 1 ISO valves (G 3/8)

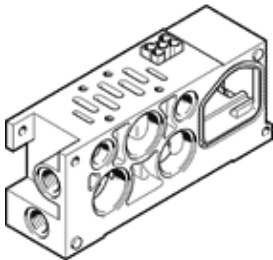

Data sheet

Feature	Value
Based on the standard	ISO 5599-2
Max. number of valve positions	1
Operating pressure	-0.9 ... 16 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Medium temperature	-10 ... 60 °C
Ambient temperature	-10 ... 60 °C
Mounting method for sub-base	with through hole
Pneumatic connection, port 1	G1/2
Pneumatic connection, port 2	G3/8
Pneumatic connection, port 3	G1/2
Pneumatic connection, port 4	G3/8
Pneumatic connection, port 5	G1/2
Materials information for sub-base	Aluminium die cast