 



**silencer**  
**UC-QS-10H**  
Part number: 526475

FESTO

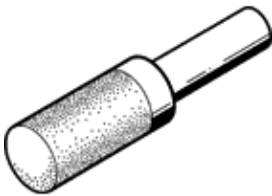

## Data sheet

Feature	Value
Assembly position	Any
Container size	1
Operating pressure MPa	0 ... 1 MPa
Operating pressure	0 ... 10 bar
Flow rate to atmosphere	3,100 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7::-]
Note on operating and pilot medium	Lubricated operation possible
PWIS conformity	VDMA24364-B1/B2-L
Sound pressure level	68 dB(A)
Ambient temperature	-10 ... 70 °C
Product weight	5.5 g
Pneumatic connection	QS-10
Material of silencer insert	PE
Material of threaded plug	PE
Materials note	Conforms to RoHS