


quick coupling plug KS5-1/2-A

Part number: 531687
Product to be discontinued

FESTO

For self-closing quick coupling connectors.

Type to be discontinued. Available until 2019. See Support Portal for alternative products.

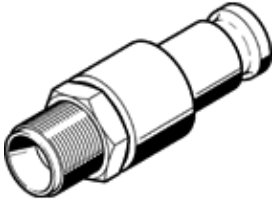

Data sheet

Feature	Value
Nominal size	13 mm
Operating pressure complete temperature range	0 ... 12 bar
Standard nominal flow rate	1,872 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-10 ... 60 °C
Nominal tightening torque	32.5 Nm
Tolerance for nominal tightening torque	± 20 %
Product weight	255 g
Pneumatic connection, port 1	Male thread G1/2