 



Branching module MS4N-FRM-1/8-Z

Part number: 531952

FESTO

Direction of flow: from right to left.

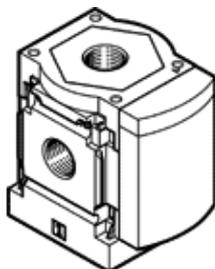

Data sheet

Feature	Value
Assembly position	Any
Design structure	Branching module
Operating pressure	0 ... 14 bar
Standard nominal flow rate in main flow direction 1->2	1,800 l/min
Standard nominal flow rate outlet at top	1,600 l/min
Standard nominal flow rate outlet at bottom	1,700 l/min
Operating medium	Compressed air
Corrosion resistance classification CRC	2
Storage temperature	-10 ... 60 °C
Medium temperature	-10 ... 60 °C
Ambient temperature	-10 ... 60 °C
Product weight	165 g
Pneumatic connection, port 1	NPT1/8-27
Pneumatic connection, port 2	NPT1/8-27
Pneumatic connection, port 3	NPT1/4-18
Pneumatic connection, port 4	NPT1/4-18
Materials information, housing	Aluminium die cast