 



# branching module MS4N-FRM-1/4-Y

Part number: 531953

FESTO

Includes pressure switch without indicator, direction of flow: from left to right.

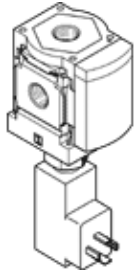

## Data sheet

Feature	Value
Assembly position	Any
Design structure	Branching module
Operating pressure	0 ... 12 bar
Standard nominal flow rate in main flow direction 1->2	4,600 l/min
Standard nominal flow rate outlet at top	1,500 l/min
Standard nominal flow rate outlet at bottom	1,500 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4] Inert gases
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Storage temperature	-10 ... 60 °C
Food-safe	See Supplementary material information
Medium temperature	-10 ... 60 °C
Ambient temperature	-10 ... 60 °C
Product weight	405 g
Pneumatic connection, port 1	1/4 NPT
Pneumatic connection, port 2	1/4 NPT
Pneumatic connection, port 3	1/4 NPT
Pneumatic connection, port 4	1/4 NPT
Materials note	Conforms to RoHS
Material housing	Aluminium die cast