 



Branching module MS6N-FRM-1/2-Z

Part number: 531969

FESTO

Direction of flow: from right to left.

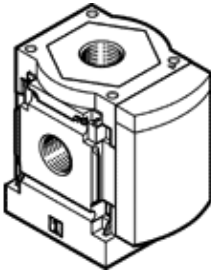

Data sheet

Feature	Value
Assembly position	Any
Design structure	Branching module
Operating pressure	0 ... 20 bar
Standard nominal flow rate in main flow direction 1->2	13,000 l/min
Standard nominal flow rate outlet at top	6,700 l/min
Standard nominal flow rate outlet at bottom	8,000 l/min
Operating medium	Compressed air
Corrosion resistance classification CRC	2
Storage temperature	-10 ... 60 °C
Medium temperature	-10 ... 60 °C
Ambient temperature	-10 ... 60 °C
Product weight	500 g
Pneumatic connection, port 1	NPT1/2-14
Pneumatic connection, port 2	NPT1/2-14
Pneumatic connection, port 3	NPT1/2-14
Pneumatic connection, port 4	NPT1/2-14
Materials information, housing	Aluminium die cast