


Push-in Y-connector QSY-F-8-6

Part number: 533936

FESTO

reducing.

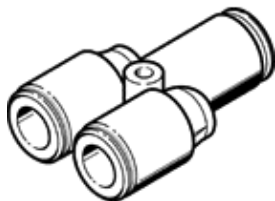

Data sheet

Feature	Value
Size	Standard
Nominal size	5.5 mm
Design structure	Push/pull principle
Operating pressure complete temperature range	-0.95 ... 16 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	3
Food safety	to manufacturer's declaration
Ambient temperature	0 ... 150 °C
Authorisation	Germanischer Lloyd
Product weight	28.1 g
Pneumatic connection, port 1	for tubing, 8mm outside diameter
Pneumatic connection, port 2	for tubing, 6mm outside diameter
Materials note	Conforms to RoHS
Materials information, housing	Brass Chromium and nickel plated
Materials information for thread seal	FPM
Materials information for tubing seal	FPM