
 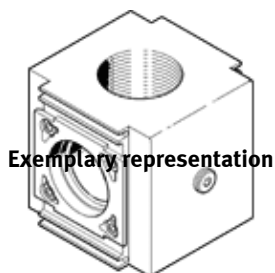


# branching module MS12-FRM

Part number: 535035

FESTO

For manifold assembly, with G thread.



Exemplary representation

## Data sheet

Overall data sheet – Individual values depend upon your configuration.

Feature	Value
Assembly position	Any
Design structure	Branching module
Operating pressure	0 ... 20 bar
Standard nominal flow rate in main flow direction 1->2	25,000 ... 42,000 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [-::-]
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Storage temperature	-10 ... 60 °C
Medium temperature	-10 ... 60 °C
Ambient temperature	-10 ... 60 °C
Pneumatic connection, port 4	G1
Material housing	Aluminium die cast