


vacuum filter VAF-PK-3

Part number: 535883

FESTO

In-line design.

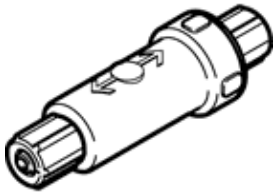

Data sheet

Feature	Value
Nominal size	2 mm
Assembly position	Any
Grade of filtration	50 µm
Operating pressure	-0.95 ... 0 bar
Note on operating pressure	Only for application in open vacuum systems
Flow rate at negative pressure of -0.075 MPa (-0.75 bar, -10.875 psi)	50.8 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:::]
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	0 ... 40 °C
Product weight	4 g
Mounting type	Line installation
Pneumatic connection	PK-3 with union nut
Material of union nut	POM
Materials note	Conforms to RoHS
Material filter	Mesh PA
Material housing	PA
Ejector pulse suitability	≤ 8 bar