


Gripper jaw blank BUB-HGPT-40-

Part number: 537202

FESTO

Suitable for HGPT-... T-slot gripper

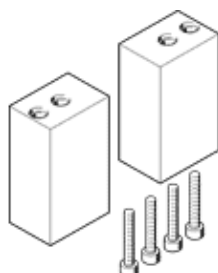

Data sheet

| Feature | Value |
|---|---------------------------------------|
| Size | 40 |
| Assembly position | Any |
| Corrosion resistance classification CRC | 2 |
| Ambient temperature | 5 ... 60 °C |
| Product weight per gripper jaw | 314 g |
| Mounting type | With through-hole and centring sleeve |
| Materials note | Free of copper and PTFE |
| Material information, unmachined part | Wrought Aluminium alloy |