

Plastic tubing


PUN-E-4x0,6-SW-500

Part number: 538460

FESTO

Suitable for use with QS push-in connectors, highly flexible, hydrolysis resistant, micron stable, approved for use in food processing.

Type to be discontinued. Available until 2012.

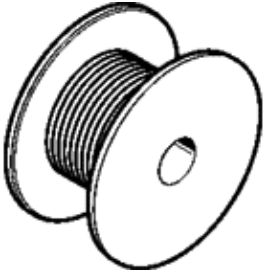

Data sheet

Feature	Value
Outside diameter	4 mm
Bending radius relevant for flow rate	30 mm
Inside diameter	2.8 mm
Min. bending radius	8 mm
Temperature dependent operating pressure	-0.95 ... 8 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7::-:]
Food-industry approval	FDA 2002/72/EG
Ambient temperature	-35 ... 50 °C
Product weight according to length	0.008 kg/m
Colour	Black
Shore hardness	D 52 +/-3
Materials note	Free of copper and PTFE Conforms to RoHS
Materials information for tubing	TPE-U(PU)