


plug socket MSSD-EB-M12

Part number: 539712

FESTO

For solenoid coils and valves, port pattern per DIN EN 175 301, type C.

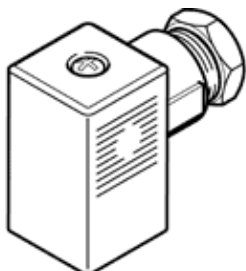

Data sheet

Feature	Value
Connection frequency	50
Mounting type	On solenoid valve with M2.5 central screw
Assembly position	Any
Product weight	11 g
Electrical connection	3-pin Plug socket angled Plug pattern type C to EN 175301-803 Per DIN EN 175301-803 Cubic design
Cable gland connection	M12
Permissible cable diameter	4 ... 6 mm
Terminal cross-section	1.5 mm ²
Protection class	IP65 to IEC 60529
Ambient temperature	-40 ... 125 °C
PWIS conformity	VDMA24364-B2-L
Material housing	PA-reinforced
Material seals	HNBR