


# Bus interface SPC200-COM-DN2

Part number: 540305

FESTO

enables activation via the DeviceNet fieldbus with the protocol versions DeviceNet IO or DeviceNet Profile.

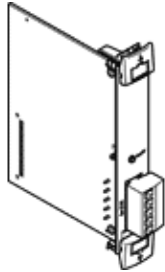

## Data sheet

Feature	Value
Number of outputs at set selection	2 byte
Number of outputs at start/stop	2 ... 8 byte
Number of inputs at set selection	4 byte
Number of inputs at start/stop	2 ... 8 byte
supported operation modes	Start/Stop Set selection
Operation characteristics	reading and writing inputs/outputs reading and writing all program registers reading the actual entries digital setpoint specification
Device setup	DeviceNet interface
Configuration support	EDS file
Device-specific diagnostics	via status byte via WinPISA
Power supply fieldbus DC	11 ... 30 V
Typical current consumption, plug-in module	50 mA
Ambient temperature	-5 ... 50 °C
Product weight	80 g
Fieldbus interface address range	0 ... 63 °C
Fieldbus interface design	protocol versions: Device Net IO and Device Net Profile Electrical isolation Layer 1 per ISO/DIS 11898 Standard high-speed to 1 Mbit Layer 2 per CAN specification V2.0 Device Net Release 2.0 125, 250, 500 kBaud
Electrical connection, fieldbus interface	Terminal strip 5-pin Open style:
Product-specific LED display	Module and network status display
Installation space	From 3 up
Materials note	Contains PWIS substances