 



push-in T-connector NEDU-M12D5-M12T4

Part number: 541596

FESTO

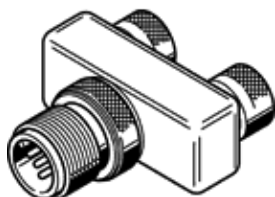

Data sheet

Feature	Value
Assembly position	Any
Connection frequency	500
Operating voltage range AC	250 V
Operating voltage range DC	250 V
Nominal operating voltage, AC	250 V
Nominal operating voltage DC	60 V
Permissible current load	4 A
Corrosion resistance classification CRC	2
Storage temperature	-25 ... 85 °C
Protection class	IP65 IP67
Ambient temperature	-25 ... 85 °C
Max. tightening torque	0.5 Nm
Product weight	25.5 g
Electrical connection	to EN 60947-5-2 Plug/socket M12x1 / M12x1 4-pin / 4-pin A-coded / A-coded
Mounting type	Threaded
Housing colour	Black
Materials information for locknut	Brass Chromed-plated Nickel plated
Materials note	Free of copper and PTFE
Materials information, housing	TPE-U (PU), amplified
Material information for crimp connectors	Brass Gold plated